

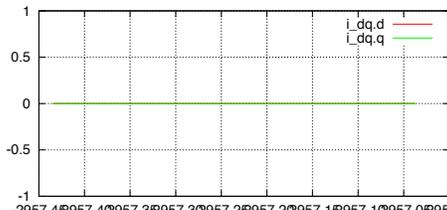
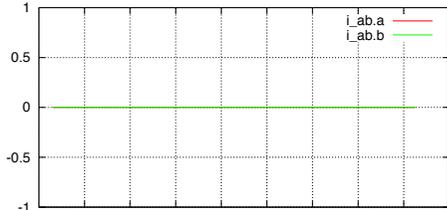
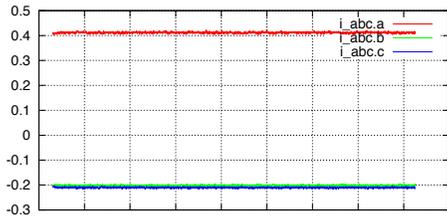
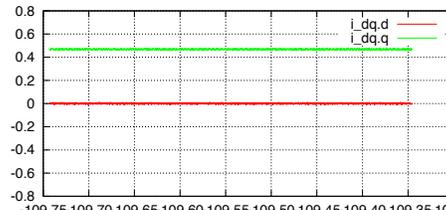


PMSMVC Currents: During alignment

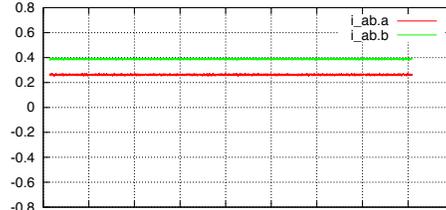




-2957.42957.402957.382957.362957.342957.322957.302957.282957.262957.242957.222957.202957.182957.162957.142957.122957.102957.082957.062957.042957.022957.00

PMSMVC Currents: 0, 180 degree Torque=600

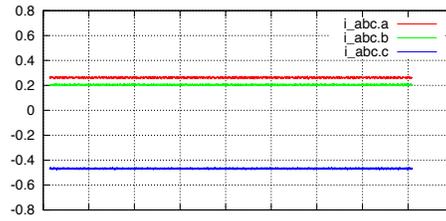




-109.75-109.70-109.65-109.60-109.55-109.50-109.45-109.40-109.35-109.30

PMSMVC Currents: 90, 270 degree Torque=600

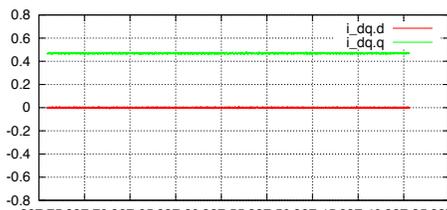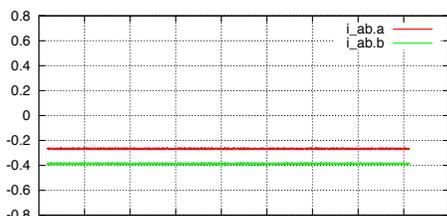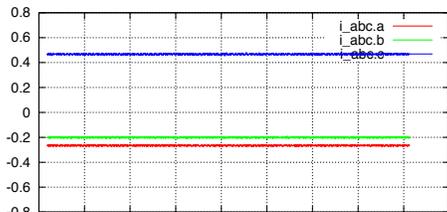

-887.75-887.70-887.65-887.60-887.55-887.50-887.45-887.40-887.35-887.30

PMSMVC Currents: spinning Torque=600

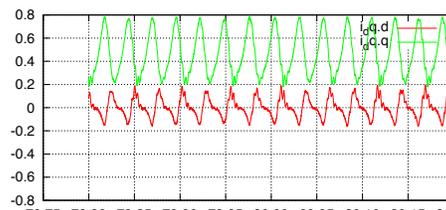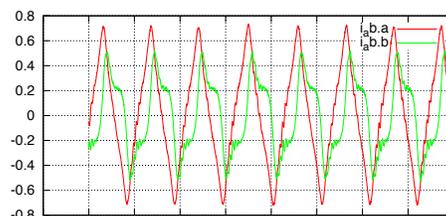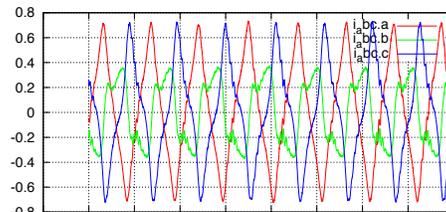

79.75 79.80 79.85 79.90 79.95 80.00 80.05 80.10 80.15 80.20